


CONNECTIONS

DC Motors

Permanent Magnet Type Direct Current Motor
90vdc or 180vdc (see nameplate) for Adjustable
Speed Control.

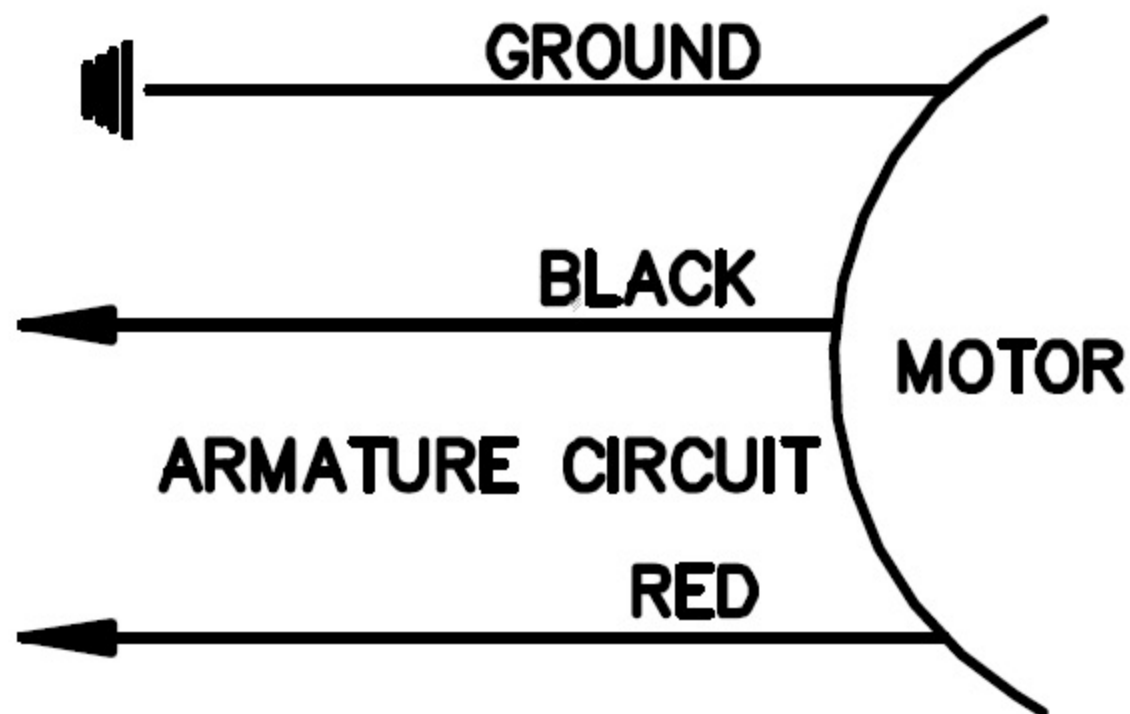

TO REVERSE ROTATION INTERCHANGE THE RED AND BLACK LEADS